



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	1
Plug	Plug - Straight
Locking system	Push-pull
Size	00

https://www.lemo.com/int_en/ffm-00-130-lc.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	1
--------------------------------	---

Form & Material

Shell style / Model id	FF - Straight plug, non-latching, cable collet
Plug	Straight
Housing material	Aluminum alloy (anodized) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	1.1 g


Environment

Environmental sealing (IP rating)	IP50
-----------------------------------	------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

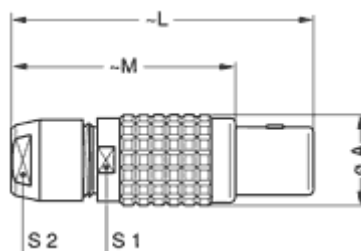

Dimensions

	L	S2	A	M	S1
mm.	24	6	12	16	5.5
in.	0.94	0.24	0.47	0.63	0.22

https://www.lemo.com/int_en/ffm-00-130-1c.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.