

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Protocol	USB 2.0 (480Mb/s)
Wire Size/AWG	24 - 20
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.10 - 5.50 mm
Size	1K
Suggested matching part	<a href="#">EGA.1K.304.CYM</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	4.8 mOhm
Insert configuration value	1K.304 - 4 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	10 A
Vtest (contact-contact)	1700 V (AC), 2400 V (DC)
Vtest (contact-shell)	1800 V (AC), 2550 V (DC)
Contact retention	30 N
Contact Type	Crimp
Max. Conductor	0.5 mm <sup>2</sup> (AWG 20)
Min. Conductor	0.25 mm <sup>2</sup> (AWG 24)
Bucket Dia.	1.1 mm (0.043in)
Contact Dia.	0.9 mm (0.035in)
Number of contacts Low Voltage	4
Protocol	USB 2.0 (480Mb/s)
Wire Size/AWG	24 - 20
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	2 keys (alpha=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	23.74 g

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.10 - 5.50 mm

## Drawings

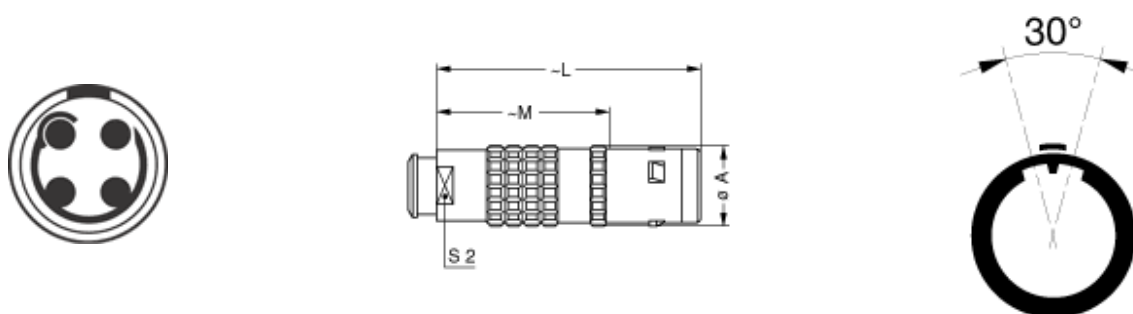

## Dimensions

	<b>M</b>	<b>A</b>	<b>S2</b>	<b>L</b>
mm.	28	13	9	42
in.	1.1	0.51	0.35	1.65

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Accessories

Replacement contact	<a href="#">FGG.1B.560.ZZC</a>
---------------------	--------------------------------

## Tools





Positionner	<a href="#">DCE.91.091.BVC</a>
-------------	--------------------------------

Extraction tool	<a href="#">DCC.09.05B.LAG</a>
-----------------	--------------------------------

Crimp tool	<a href="#">DPC.91.701.V</a>
------------	------------------------------

Spanner wrench	<a href="#">DCD.1E.ZZZ.PA090</a>
----------------	----------------------------------

# Cables

Cable PartNumber	Material	Colour	Cable image
CMN.04.T20.053PGZE		grey	
CMN.04.T20.053PNZE			
CMN.04.T20.053QGZE	TPR (medical)	Grey	
4080	PVC	Grey	
4220	PVC	Black	

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fga-1k-304-cycc55z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.