



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fiber optic	1
Plug	Plug - Straight
Locking system	Push-pull
Size	00

https://www.lemo.com/int_en/fgg-00-bb4-ccbe30z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Fiber optic	1
Insert configuration value	FO/BB4 - 1 FO 126 um hole
Insulator	C: Zirconia Ceramic
Core/Cladding (um)	50/125
Ferrule Material	Zirconia Ceramic
Hole dia.(um)	126
Contact Type	F4 (included)

Form & Material

Shell style / Model id	FG - Straight plug key (G) or (B) with bend relief included
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	7.79 g

Environment

Environmental sealing (IP rating)	IP50
Salt Spray Corrosion	>1000 hr


Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Crimp

Drawings

https://www.lemo.com/int_en/fgg-00-bb4-ccbe30z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

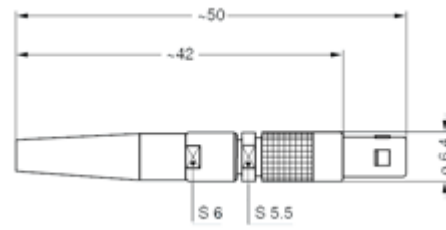

Dimensions

	A	L	M	S1	S2
mm.	6.4	50	42	5.5	6
in.	0.25	1.97	1.65	0.22	0.24

Recommended By Lemo

Accessories

Compatible cap

[BFG.00.100.PCSG](#)

https://www.lemo.com/int_en/fgg-00-bb4-ccbe30z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.