



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fluidic	1
Jacket cable outside diameter [mm]	1.60 - 6.20 mm
Size	0R
Suggested matching part	EGG.0R.010.AZL05

https://www.lemo.com/int_en/fgg-0r-010-aza05.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Fluidic	1
Contact Termination Fluidic	Solder
Contact Type	Solder

Form & Material

Shell style / Model id	FGG - Male fluidic / pneumatic contact
Housing material	Stainless steel
Keying	No keying
Weight	0.53 g


Environment

Environmental sealing (IP rating)	No IP rating
-----------------------------------	--------------

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Jacket cable outside diameter [mm]	1.60 - 6.20 mm

Drawings

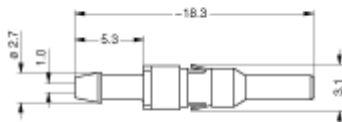

No keying

https://www.lemo.com/int_en/fgg-0r-010-aza05.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.