

Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Number of contacts Low Voltage	1
Wire Size/AWG	28 - 20
Gender	Standard
Plug	Plug - Straight
Locking system	Quick-release (Snap-on)
Size	1B
Matching parts	EGG.1B.303.CLJ
Series	B - Indoor keyed

Technical details

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgg-1b-303-cljf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

Contact Termination Low voltage	Solder
Thermocouple	2
Insert configuration value	1B.303/ThC - 1 Thermocouple Pair, Ground
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	12 Amps
ThC. Materials (P+/N-)	Iron (magnetic) / Constantan
Contact Dia.	1.3
Number of contacts Low Voltage	1
Wire Size/AWG	28 - 20
Gender	Standard

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Quick-release (Snap-on)
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	15.7 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgg-1b-303-cljf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation


Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

Drawings

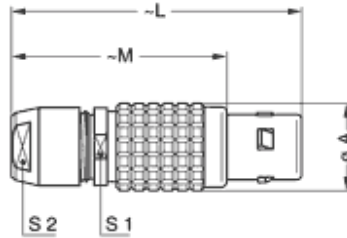

Dimensions

	A	L	M	S1	S2
mm.	12	43	32	10	9
in.	0.47	1.69	1.26	0.39	0.35

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgg-1b-303-cljf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.