



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	6
Wire Size/AWG	30 - 22
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.60 - 6.00 mm
Size	1T
Suggested matching part	<a href="#">EGG.1T.306.CYK</a>
Series	T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Thermocouple	6
Contact Termination Thermocouple	Crimp
Insert configuration value	1T.306 - 3 Thermocouple Pairs
Insulator	Y: PEEK for crimp contacts
Rated current	7 A
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	0.7
Wire Size/AWG	30 - 22
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

 
 

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.60 - 6.00 mm

Drawings

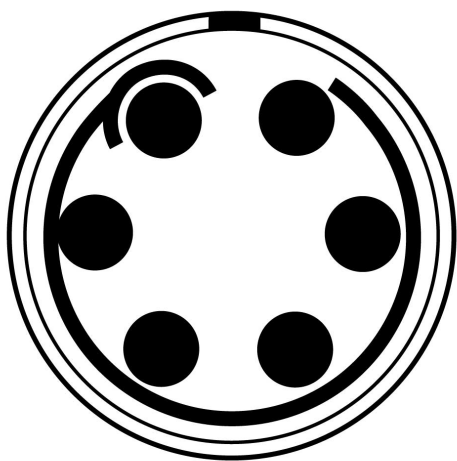

Contact 1, 3, 5: Chromel (+)  
Contact 2, 4, 6: Alumel (-)

Dimensions

	A	L	M	S1	S2
mm.	12	46	35	11	9
in.	0.47	1.81	1.38	0.43	0.35

Recommended By Lemo

Accessories

Compatible cap [BFG.1T.100.CAS](#)

Tools

Spanner [DCP.0T.110.TN](#)

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-1t-306-cykc60.html)  
LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.