



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Plug	Plug - Straight
Locking system	Push-pull
Size	2G

https://www.lemo.com/int_en/fgg-2g-d6j-cla31.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Insulator	L: PEEK (UL 94 / V-0/1.5)
-----------	---------------------------

Form & Material

Shell style / Model id	FGG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	19.63 g


Environment

Environmental sealing (IP rating)	IP50
Endurance	500 mating cycles
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

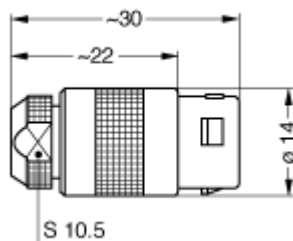

Dimensions

	A	L	M	S2
mm.	14	30	22	10.5
in.	0.55	1.18	0.87	0.41

https://www.lemo.com/int_en/fgg-2g-d6j-cla31.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.