

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Size	2L
Matching parts	PHG.2L.304.CLLC70

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Rated current	15 Amps
Contact Type	Solder
Contact Dia.	1.3
Number of contacts Low Voltage	4
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/fgg-2l-304-clac70.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Weight	40.08 g


Environment

Environmental sealing (IP rating)	IP66
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

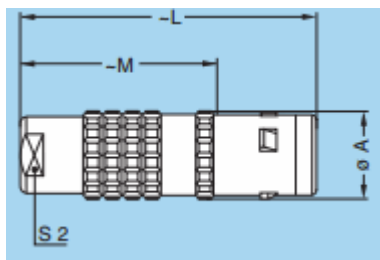

Dimensions

	A	L	M	S2
mm.	16	52	36	12
in.	0.63	2.05	1.42	0.47

https://www.lemo.com/int_en/fgg-2l-304-clac70.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.