



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Wire Size/AWG	24 - 24
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.30 - 6.20 mm
Size	2T
Series	T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Insulator	L: PEEK (UL 94 / V-0/1.5)
Wire Size/AWG	24 - 24
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	32.94 g

## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr



## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.30 - 6.20 mm

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

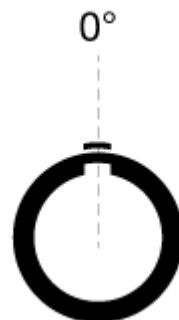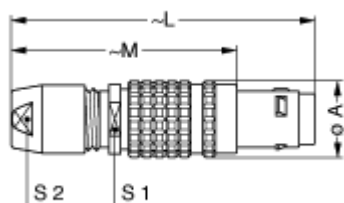

## Dimensions

	<b>A</b>	<b>L</b>	<b>M</b>	<b>S1</b>	<b>S2</b>
mm.	15	55	43	14	12
in.	0.59	2.17	1.69	0.55	0.47

## Recommended By Lemo

### Accessories

Compatible cap [BFG.2T.100.CAS](#)

### Tools

Spanner [DCP.2T.110.TN](#)

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgg-2t-804-clac601.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.