



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	12
Wire Size/AWG	24 - 20
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	9.60 - 10.00 mm
Size	3K
Suggested matching part	<a href="#">EGG.3K.312.CYM</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	4.8 mOhm
Insert configuration value	3K.312 - 12 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	9 A
Vtest (contact-contact)	1650 V (AC), 2350 V (DC)
Vtest (contact-shell)	1850 V (AC), 2600 V (DC)
Contact retention	30 N
Contact Type	Crimp
Max. Conductor	0.5 mm <sup>2</sup> (AWG 20)
Min. Conductor	0.25 mm <sup>2</sup> (AWG 24)
Bucket Dia.	1.1 mm (0.043in)
Contact Dia.	0.9 mm (0.035in)
Number of contacts Low Voltage	12
Wire Size/AWG	24 - 20
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	66.79 g

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	9.60 - 10.00 mm

## Drawings

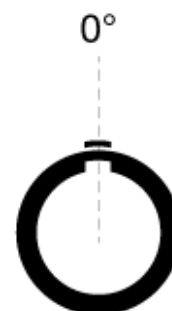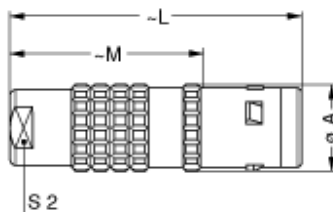

## Dimensions

	<b>A</b>	<b>L</b>	<b>S2</b>	<b>M</b>
mm.	19	61	15	41
in.	0.75	2.4	0.59	1.61

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Accessories

---

Replacement contact	<a href="#">FGG.3B.560.ZZC</a>
---------------------	--------------------------------

---

Compatible cap	<a href="#">BFG.3K.100.NAS</a>
----------------	--------------------------------

## Tools

---

Positionner	<a href="#">DCE.91.093.BVC</a>
-------------	--------------------------------

---

Extraction tool	<a href="#">DCC.09.05B.LAG</a>
-----------------	--------------------------------

---

Crimp tool	<a href="#">DPC.91.701.V</a>
------------	------------------------------

---

Spanner wrench	<a href="#">DCD.3E.ZZZ.PA150</a>
----------------	----------------------------------

# Cables

Cable PartNumber	Material	Colour	Cable image
412500	PVC	Grey	

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-312-cycc10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.