



## Summary

[Request a quote](#)

[Catalog](#)

Fiber optic	12
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Size	5K
Series	K - Outdoor keyed

## Technical details

### Electrical Configuration

Fiber optic	12
Insulator	L: PEEK (UL 94 / V-0/1.5)
Gender	Standard

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	329.24 g



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet

## Drawings

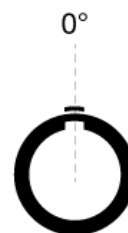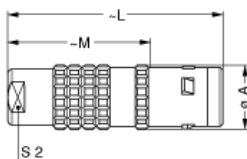

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>A</b>	<b>L</b>	<b>S2</b>	<b>M</b>
mm.	38	92	30	67
in.	1.5	3.62	1.18	2.64

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-5k-956-clyz.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.