



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Wire Size/AWG	24 - 16
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.30 - 6.20 mm
Size	2T
Suggested matching part	<a href="#">EGL.2T.303.CLA</a>
Series	T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	3
Contact Termination Low voltage	Solder
R (max)	3.5 mOhm
Insert configuration value	T.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	17 A
Vtest (contact-contact)	3.5 kV (DC)
Vtest (contact-shell)	2.6 kV (DC)
Max. Solid Conductor	1 mm <sup>2</sup> (AWG 16)
Max. Stranded Conductor	1 mm <sup>2</sup> (AWG 18)
Bucket Dia.	1.4 mm (0.055in)
Contact Dia.	1.6 mm (0.063in)
Wire Size/AWG	24 - 16
Gender	Reverse Gender

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	L: 2 keys (gamma=70, plug: female contacts, receptacle: male contacts)
Colour	Grey

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.30 - 6.20 mm

## Drawings

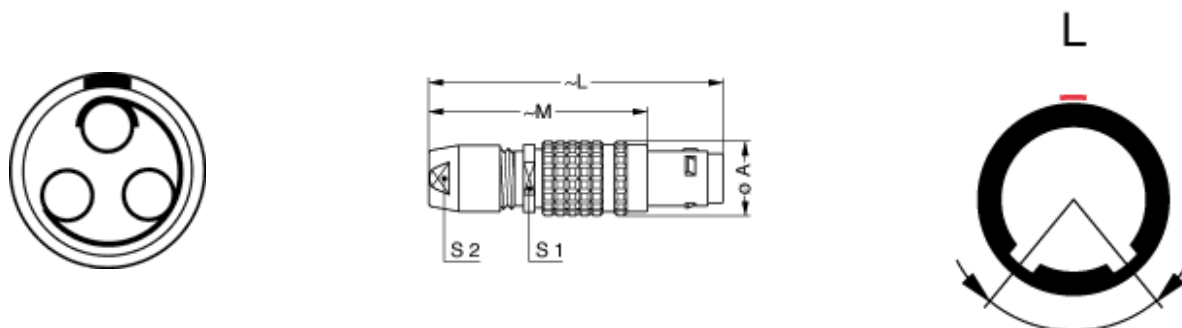

## Dimensions

	A	L	M	S1	S2
mm.	15	55	43	14	12
in.	0.59	2.17	1.69	0.55	0.47





[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-2t-303-cllc60.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

Accessories	
Compatible cap	<a href="#">BFG.2T.100.CAS</a>
Tools	
Spanner	<a href="#">DCP.2T.110.TN</a>

## Cables

Cable PartNumber	Material	Colour	Cable image
CMN.03.T18.055PGZE		grey	
CMN.03.T18.055PNZE			
CMN.03.T18.055QGZE	TPR (medical)	Grey	
230500	PVC	Grey	
230750	PVC	Grey	