

## Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Low Voltage	1
Wire Size/AWG	22 - 14
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.10 - 7.50 mm
Size	3K
Series	K - Outdoor keyed

## Technical details

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination Low voltage	Solder
Thermocouple	2
Insert configuration value	3K.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	25 Amps
Contact Dia.	2 mm (0.079" in)
Low Voltage	1
Wire Size/AWG	22 - 14
Gender	Reverse Gender

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet, gasket and O-ring in EPDM
Plug	Straight
Housing material	Stainless steel shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=75, plug: female contacts, receptacle: male contacts)
Variant	Gasket and O-ring in EPDM
Weight	64.24 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	IP68
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]



[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.10 - 7.50 mm

## Drawings

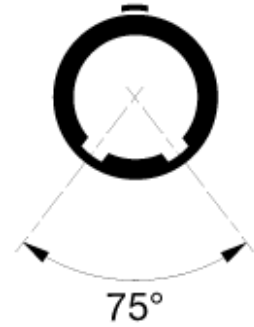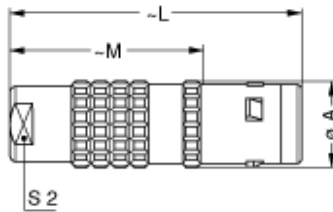

## Dimensions

	<b>S2</b>	<b>M</b>	<b>L</b>	<b>A</b>
mm.	15	41	61	19
in.	0.59	1.61	2.4	0.75

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-303-tlkc75e.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.