



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	24
Wire Size/AWG	26 - 22
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	10.10 - 10.50 mm
Size	3T
Suggested matching part	<a href="#">EGL.3T.324.CYC</a>
Series	T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	24
Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	T.324 - 24 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	4 A
Vtest (contact-contact)	2 kV (DC)
Vtest (contact-shell)	2 kV (DC)
Contact retention	22 N
Max. Conductor	0.34 mm <sup>2</sup> (AWG 22)
Min. Conductor	0.14 mm <sup>2</sup> (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	26 - 22
Gender	Reverse Gender

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	L: 2 keys (gamma=70, plug: female contacts, receptacle: male contacts)
Colour	Grey

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.10 - 10.50 mm

## Drawings

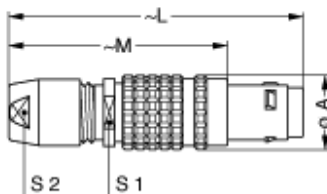

## Dimensions

	A	L	M	S1	S2
mm.	18.8	64	49	16	14
in.	0.74	2.52	1.93	0.63	0.55

 
[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fgl-3t-324-cymc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

Accessories	
Replacement contact	<a href="#">EGG.3B.655.ZZW</a>
Compatible cap	<a href="#">BFG.3T.100.CAS</a>
Tools	
Spanner	<a href="#">DCP.2T.110.TN</a>
Positionner	<a href="#">DCE.91.073.BVM</a>
Extraction tool	<a href="#">DCC.07.04B.LAG</a>
Crimp tool	<a href="#">DPC.91.701.V</a>

## Cables

Cable PartNumber	Material	Colour	Cable image
324220	PVC	Black	
424250	PVC	Grey	