



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fiber optic	2
Wire Size/AWG	30 - 22
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Size	3B
Suggested matching part	<a href="#">ENY.3B.97J.PLLB</a>
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Fiber optic	2
Insert configuration value	3B.97J - 2 FO Type F1, 10 LV
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	6 A
Contact Dia.	0.7
Wire Size/AWG	30 - 22
Gender	Standard

## Form & Material

Shell style / Model id	FGY - Straight plug, cable collet and PSU or PPSU outer shell
Plug	Straight
Housing material	PSU (Polysulfone) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (beta=126, gamma=102, plug: male contacts, receptacle: female contacts)

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-50°C / +150°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation



Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

## Drawings

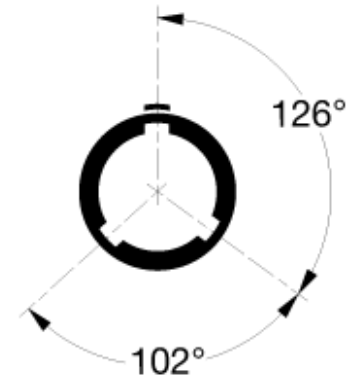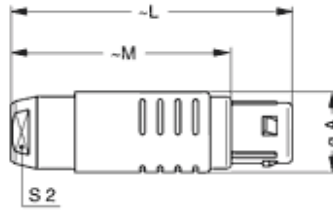

## Dimensions

	<b>S2</b>	<b>M</b>	<b>L</b>	<b>A</b>
mm.	15	43	58	19
in.	0.59	1.69	2.28	0.75

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgy-3b-97j-plyd8zb.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.