



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

|                                    |                                |
|------------------------------------|--------------------------------|
| Number of contacts Low Voltage     | 2                              |
| Wire Size/AWG                      | 16 - 12                        |
| Gender                             | Reverse Gender                 |
| Plug                               | Plug - Elbow                   |
| Locking system                     | Push-pull                      |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm                 |
| Size                               | 2B                             |
| Suggested matching part            | <a href="#">EGJ.2B.302.CYC</a> |
| Series                             | B - Indoor keyed               |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

|                                 |                              |
|---------------------------------|------------------------------|
| Number of contacts Low Voltage  | 2                            |
| Contact Termination Low voltage | Crimp                        |
| R (max)                         | 3.3 mOhm                     |
| Insert configuration value      | 2B.302 - 2 Low Voltage       |
| Insulator                       | Y: PEEK for crimp contacts   |
| Rated current                   | 20.5 A                       |
| Vtest (contact-contact)         | 4.1 kV (DC)                  |
| Vtest (contact-shell)           | 3.8 kV (DC)                  |
| Contact retention               | 65 N                         |
| Max. Conductor                  | 2.5 mm <sup>2</sup> (AWG 12) |
| Min. Conductor                  | 1.5 mm <sup>2</sup> (AWG 16) |
| Bucket Dia.                     | 2.4 mm (0.094in)             |
| Contact Dia.                    | 2 mm (0.079in)               |
| Wire Size/AWG                   | 16 - 12                      |
| Gender                          | Reverse Gender               |

## Form & Material

|                        |   |
|------------------------|---|
| Shell style / Model id | FH - Elbow plug, cable collet and nut for fitting a bend relief   |
| Plug                   | Elbow   |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system         | Push-pull   |
| Keying                 | 2 keys (alpha=37.5, plug: female contacts, receptacle: male contacts)   |
| Colour                 | Grey  |
| Variant                | Nut for fitting a bend relief   |
| Weight                 | 43.79 g   |

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

|                                   |  |
|-----------------------------------|--|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | IP50   |
| Endurance                         | 5000 mating cycles   |
| Temperature range                 | -55°C / +250°C (max. temperature valid for short periods of use.)  |
| Climatical Category               | 50/175/21  |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]   |
| Shielding (min)                   | 75 dB (10 MHz)   |
| Shielding (min)                   | 40 dB (1 GHz)  |
| Shock Resistance                  | 100 g [ 6 ms]  |
| Vibration                         | 15 g [10 Hz - 2000 Hz]   |
| Salt Spray Corrosion              | >1000 hr   |

## Cable fixation

|                                    |                       |
|------------------------------------|-----------------------|
| Cable termination protection       | For cable bend relief |
| Fixation type                      | Cable collet          |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm        |

## Drawings

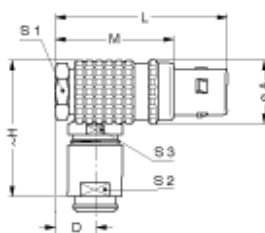

## Dimensions

|     | A    | D    | H    | L    | M    | S1   | S2   | S3   |
|-----|------|------|------|------|------|------|------|------|
| mm. | 16.5 | 9    | 34.3 | 41.5 | 29.5 | 14   | 12   | 14   |
| in. | 0.65 | 0.35 | 1.35 | 1.63 | 1.16 | 0.55 | 0.47 | 0.55 |





[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fhj-2b-302-cymd62z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

| Accessories         |                                  |
|---------------------|----------------------------------|
| Replacement contact | <a href="#">EGG.2B.675.ZZM</a>   |
| Tools               |                                  |
| Positionner         | <a href="#">DCE.91.202.BVCM</a>  |
| Extraction tool     | <a href="#">DCC.20.25B.LAG</a>   |
| Crimp tool          | <a href="#">DPC.91.101.A</a>     |
| Spanner wrench      | <a href="#">DCD.2B.ZZZ.PA120</a> |

## Cables

| Cable PartNumber | Material | Colour | Cable image   |
|------------------|----------|--------|---|
| 102080           | PVC      | Grey   |   |
| 120184           | PVC      | Black  |    |
| 120500           | PVC      | Grey   |   |
| 120751           | PVC      | Grey   |  |
| 220750           | PVC      | Grey   |  |