

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

00and01Coaxial en

Nb of contacts Coax	1
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.80 - 3.10 mm
Size	00
Suggested matching part	ERA.00.250.CTL
Series	00 - NIM-CAMAC

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Contact Termination Coax - Screen fixing	Cable collet
R (max)	6.1 mOhm
Insert configuration value	00.25 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	4 A
Impedance	50 Ohms
VSWR	$1.09 + 0.11 * f/\text{GHz}$
Vtest	2100 V (AC), 3000 V (DC)
Test voltage	2.1 kV (rms)
Cable type	RG 179 B/U
Bucket Dia.	0.6 mm (0.024in)
Contact Dia.	0.7 mm (0.028in)

Form & Material

Shell style / Model id	FLA - Elbow plug, cable collet and nut for fitting a bend relief
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	5.4 g

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
F ret (min)	100 N
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.80 - 3.10 mm

Drawings

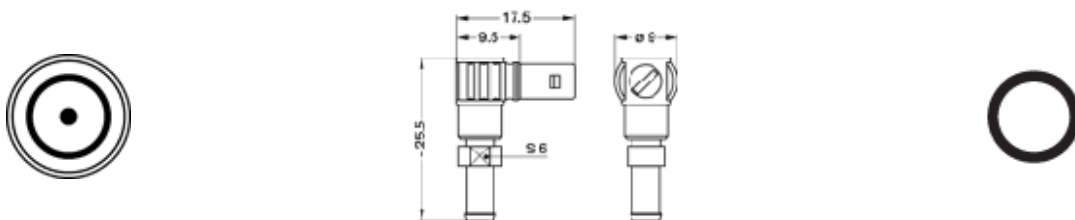

Dimensions

	A	L	M	S2
mm.	9	17.5	9.5	4.5
in.	0.35	0.69	0.37	0.18

Recommended By Lemo



Accessories

Compatible cap	BFG.00.100.PCSG
----------------	---------------------------------

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
17420	PVC	Black	
31600	PTFE	Brown	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG3.16U28M	PTFE	Brown	

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fla-00-250-ctac31z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.