



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	18 - 10
Gender	Reverse Gender
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	12.60 - 13.50 mm
Size	4N
Series	N - Nuclear Stainless Steel

https://www.lemo.com/int_en/solutions/supreme/n-nuclear-stainless-steel/fmy-4n-304-tlly13.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Solder
R (max)	3.1 mOhm
Insert configuration value	4N.304 - 4 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	30 A
Max. Solid Conductor	4 mm ² (AWG 10)
Max. Stranded Conductor	4 mm ² (AWG 12)
Bucket Dia.	2.7 mm (0.106in)
Contact Dia.	3 mm (0.118in)
Wire Size/AWG	18 - 10
Gender	Reverse Gender

Form & Material

Shell style / Model id	FMY - Elbow plug (120°) for lever with positioning pin, cable clamp and rough hanging surface
Plug	Elbow
Housing material	Stainless steel shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Push-Pull latch with additional lever. Female contacts
Colour	Grey
Variant	Special part (contact LEMO for details)
Weight	494.64 g

Environment

Technical domain	Energy and Industrial, Specialties and Other
Environmental sealing (IP rating)	IP66



https://www.lemo.com/int_en/solutions/supreme/n-nuclear-stainless-steel/fmy-4n-304-tlly13.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	12.60 - 13.50 mm

Drawings

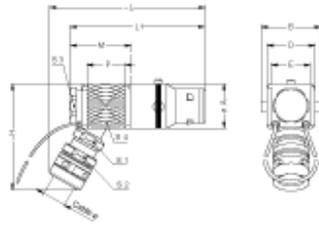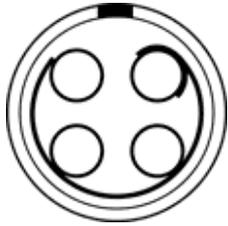

Dimensions

	A	B	D	E	H	L	L1	M	P	S1	S2	S3	S4
mm.	31	44	36	30	76.8	109.2	93	42.5	23	22	25	24	30
in.	1.22	1.73	1.42	1.18	3.02	4.3	3.66	1.67	0.91	0.87	0.98	0.94	1.18

https://www.lemo.com/int_en/solutions/supreme/n-nuclear-stainless-steel/fmy-4n-304-tlly13.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.