



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fiber optic	4
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	9.10 - 10.50 mm
Size	4B
Suggested matching part	<a href="#">EGG.4B.03C.CLZ</a>
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Fiber optic	4
Insert configuration value	4B.03C - 4 FO Type F2 (<= 140 um)
Insulator	L: PEEK (UL 94 / V-0/1.5)
Gender	Standard

## Form & Material

Shell style / Model id	FN - Straight plug, cable collet and lanyard release
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	114.59 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	9.10 - 10.50 mm

## Drawings

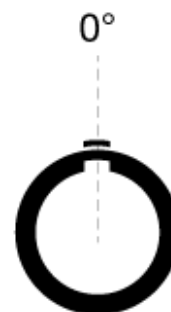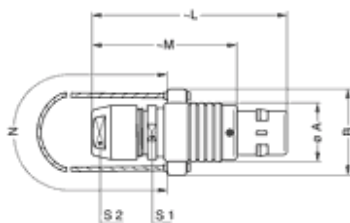

## Dimensions

	<b>N</b>	<b>S1</b>	<b>S2</b>	<b>M</b>	<b>L</b>	<b>B</b>	<b>A</b>
mm.	230	21	20	57	75	35.2	25
in.	9.06	0.83	0.79	2.24	2.95	1.39	0.98

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fng-4b-03c-clzd10.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.