



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	30 - 22
Gender	Reverse Gender
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.30 - 6.20 mm
Size	1B
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cyzd62.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cyzd62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Insert configuration value	1B.304 - 4 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	10 A
Contact Type	No contact(s)
Contact Dia.	0.9
Number of contacts Low Voltage	4
Number of differentiated pairs (High speed)	1
Wire Size/AWG	30 - 22
Gender	Reverse Gender

## Form & Material

Shell style / Model id	FP - Elbow (90°) plug with cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=45, plug: female contacts, receptacle: male contacts)
Colour	Grey

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cydz62.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cydz62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	5.30 - 6.20 mm

## Drawings

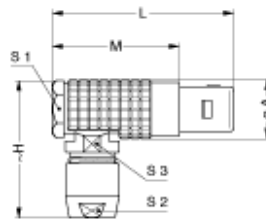

## Dimensions

	<b>A</b>	<b>H</b>	<b>L</b>	<b>M</b>	<b>S1</b>	<b>S2</b>	<b>S3</b>
mm.	12	29	36	25	11	9	10
in.	0.47	1.14	1.42	0.98	0.43	0.35	0.39

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cydz62.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fpj-1b-304-cydz62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.