



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Gender	Standard
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.10 - 7.50 mm
Size	2T
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fsa-2t-310-cycc75.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max)	4.8 mOhm
Rated current	8 A
Vtest (contact-contact)	2.6 kV (DC)
Vtest (contact-shell)	3 kV (DC)
Contact retention	30 N
Max. Conductor	0.5 mm ² (AWG 20)
Min. Conductor	0.25 mm ² (AWG 24)
Bucket Dia.	1.1 mm (0.043in)
Contact Dia.	0.9 mm (0.035in)
Gender	Standard

Form & Material

Shell style / Model id	FS - Adjustable right angle Anglissimo plug (8 selective positions) with cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	A: 2 keys (alpha=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	34.23 g

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fsa-2t-310-cycc75.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [6 ms]
Salt Spray Corrosion	>1000 hr
Note	Cable diameter is specific for Anglissimo to enable easy termination of connector

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.10 - 7.50 mm

Drawings

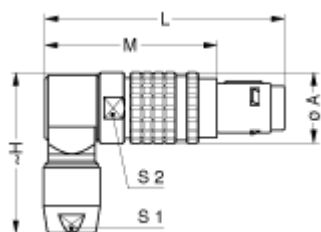

Dimensions

	A	H	L	M	S1	S2
mm.	17	37.5	54	42	12	16
in.	0.67	1.48	2.13	1.65	0.47	0.63

https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/fsa-2t-310-cycc75.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Replacement contact	FGG.2B.560.ZZC
Compatible cap	BFG.2T.100.CAS
Tools	
Positionner	DCE.91.092.BVC
Extraction tool	DCC.09.05B.LAG
Crimp tool	DPC.91.701.V

Cables

Cable PartNumber	Material	Colour	Cable image
110220	PVC	Black	