



Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Locking system	Push-pull
Size	0S
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Thermocouple	2
Insert configuration value	0S.302 - 2 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 Amps
Contact Type	Thermocouple
Contact Dia.	0.9

Form & Material

Shell style / Model id	FTA - T-plug with two in line receptacles
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	17.41 g


https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/fta-0s-302-clf.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Drawings

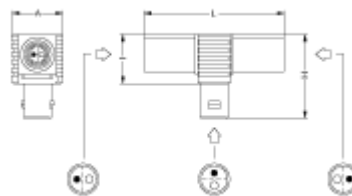

Dimensions

	A	H	I	L
mm.	13	23	13	38
in.	0.51	0.91	0.51	1.5

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/fta-0s-302-clf.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.