



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	13
Gender	Standard
Plug	Plug - Straight
Locking system	Threaded
Jacket cable outside diameter [mm]	10.60 - 12.00 mm
Size	4W
Series	W - Underwater

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	Solder
Contact Type	Solder
Number of contacts Low Voltage	13
Gender	Standard

## Form & Material

Shell style / Model id	FV_/Z - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	G: 1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	169.41 g

## Environment

Technical domain	Specialties and Other
Environmental sealing (IP rating)	IP68
Endurance	1000 mating cycles
Temperature range	-20°C / +200°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>1000 hr



[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.60 - 12.00 mm

## Drawings

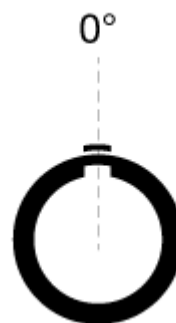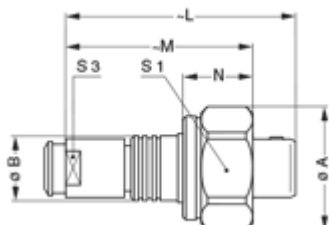

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>M</b>	<b>N</b>	<b>S1</b>	<b>S3</b>
mm.	34.3	22	71.5	57.5	17.5	32	19
in.	1.35	0.87	2.81	2.26	0.69	1.26	0.75

## Recommended By Lemo

### Accessories

Compatible cap

[BFG.4W.100.NAZ](#)

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/fvg-4w-313-crac11z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.