



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size

00

https://www.lemo.com/int_en/gma-00-025-rg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	GMA - Bend relief Grey
Housing material	Silicone elastomer VMQ
Keying	No keying
Colour	Grey
Variant	Gray
Weight	0.42 g

Environment

Environmental sealing (IP rating)	No IP rating
Temperature range in water steam	+140°C

Drawings

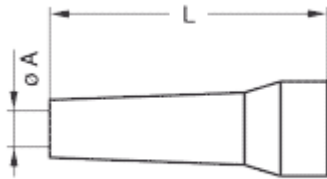

No keying

https://www.lemo.com/int_en/gma-00-025-rg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.