



## Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	4.00 - 4.40 mm
Size	0B
Series	B - Indoor keyed

## Technical details

### Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Thermoplastic polyurethane
Keying	No keying
Variant	Yellow
Weight	0.46 g

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-0b-040-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-040-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	No IP rating
Minimal temperature	-40°C / +80°C

## Cable fixation

Jacket cable outside diameter [mm]	4.00 - 4.40 mm
------------------------------------	----------------

## Drawings

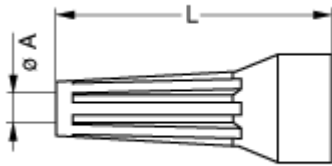

No keying

## Dimensions

	A	L
mm.	4.0	24
in.	0.16	0.94

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-0b-040-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-0b-040-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.