



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	2.50 - 2.90 mm
Size	1B
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-1b-025-rr.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-025-rr.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Form & Material

Shell style / Model id	GMA - Bend relief Red
Housing material	Silicone elastomer VMQ
Keying	No keying
Colour	Red
Variant	Red
Weight	0.93 g


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-60°C / +200°C
Temperature range in water steam	+140°C

## Cable fixation

Jacket cable outside diameter [mm]	2.50 - 2.90 mm
------------------------------------	----------------

## Drawings

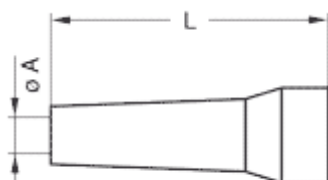

No keying

## Dimensions

	A	L
mm.	2.5	34
in.	0.1	1.34

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-1b-025-rr.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-025-rr.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.