



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|------------------|
| Jacket cable outside diameter [mm] | 3.00 - 3.40 mm |
| Size | 1B |
| Series | B - Indoor keyed |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-030-rj.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Form & Material

| | |
|------------------------|--------------------------|
| Shell style / Model id | GMA - Bend relief Yellow |
| Housing material | Silicone elastomer VMQ |
| Keying | No keying |
| Colour | Yellow |
| Variant | Yellow |
| Weight | 1.04 g |


Environment

| | |
|-----------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental sealing (IP rating) | No IP rating |
| Temperature range | -60°C / +200°C |
| Temperature range in water steam | +140°C |

Cable fixation

| | |
|------------------------------------|----------------|
| Jacket cable outside diameter [mm] | 3.00 - 3.40 mm |
|------------------------------------|----------------|

Drawings

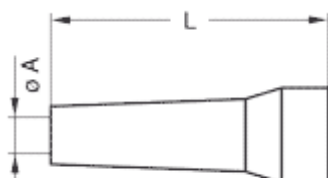

No keying

Dimensions

| | A | L |
|-----|------|------|
| mm. | 3.0 | 34 |
| in. | 0.12 | 1.34 |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-030-rj.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.