



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
Size	1B
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-045-rj.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Silicone elastomer VMQ
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	1.02 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-60°C / +200°C
Temperature range in water steam	+140°C

Cable fixation

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
------------------------------------	----------------

Drawings

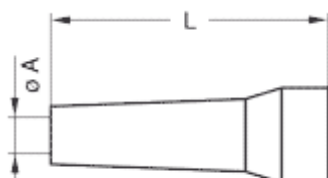

No keying

Dimensions

	A	L
mm.	4.5	34
in.	0.18	1.34

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-045-rj.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.