



## Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
Size	1B
Series	B - Indoor keyed

## Technical details

### Form & Material

Shell style / Model id	GMA - Bend relief Black
Housing material	Silicone elastomer VMQ
Keying	No keying
Variant	Black
Weight	1.01 g

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-1b-045-rn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-045-rn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental protection (IP rating)	No IP rating
Minimal temperature	-60°C / +200°C
Temperature range in water steam	+140°C

## Cable fixation

Jacket cable outside diameter [mm]	4.50 - 5.00 mm
------------------------------------	----------------

## Drawings

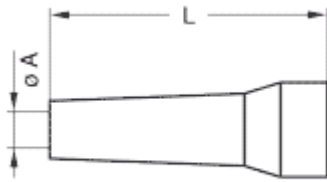

No keying

## Dimensions

	<b>A</b>	<b>L</b>
mm.	4.5	34
in.	0.18	1.34

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-1b-045-rn.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-1b-045-rn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.