



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	7.00 - 7.70 mm
Size	2B
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-2b-070-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-2b-070-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Form & Material

Shell style / Model id	GMA - Bend relief Yellow
Housing material	Thermoplastic polyurethane
Keying	No keying
Colour	Yellow
Variant	Yellow
Weight	1.92 g


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	No IP rating
Temperature range	-40°C / +80°C

## Cable fixation

Jacket cable outside diameter [mm]	7.00 - 7.70 mm
------------------------------------	----------------

# Drawings

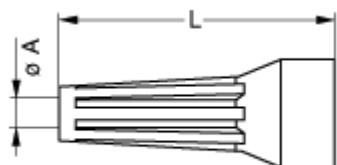

No keying

## Dimensions

	<b>A</b>	<b>L</b>
mm.	7.0	36
in.	0.28	1.42

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/gma-2b-070-dj.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/gma-2b-070-dj.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.