



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size	3K
Series	K - Outdoor keyed

Technical details


Form & Material

Shell style / Model id	GMF - Bend relief for plug
Keying	No keying
Colour	Blue
Weight	39.62 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	No IP rating
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

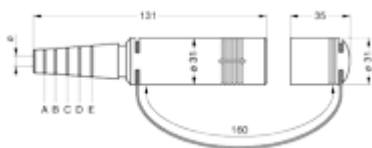

No keying