



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Jacket cable outside diameter [mm]	2.00 - 8.00 mm
Size	MP
Series	REDEL MP - Modular Inner Push-Pull

[https://www.lemo.com/int\\_en/solutions/redel/redel-mp/gmf-mp-140-sn.html](https://www.lemo.com/int_en/solutions/redel/redel-mp/gmf-mp-140-sn.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Form & Material

Shell style / Model id	GMF - Bend relief for plug, Black
Housing material	TPV (Thermoplastic vulcanizates)
Keying	No keying
Colour	Black
Weight	2.94 g


## Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	No IP rating
Temperature range	-50°C / +135°C
Steam sterilization	20 cycles

## Cable fixation

Jacket cable outside diameter [mm]	2.00 - 8.00 mm
------------------------------------	----------------

# Drawings

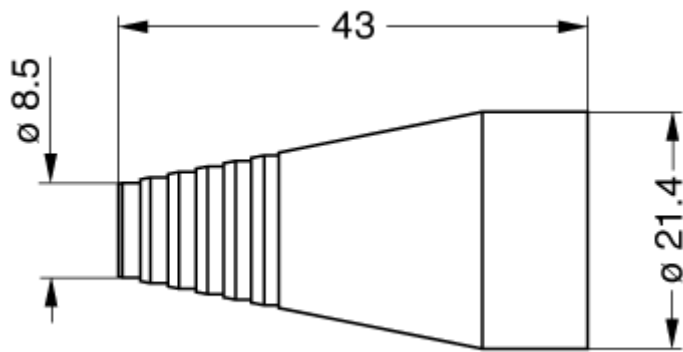

[https://www.lemo.com/int\\_en/solutions/redel/redel-mp/gmf-mp-140-sn.html](https://www.lemo.com/int_en/solutions/redel/redel-mp/gmf-mp-140-sn.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.