



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.60 - 22.60 mm
Size	3E
Series	E - Outdoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/hgp-3e-140-ctlpv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	1
Contact Termination Low voltage	Solder
Insert configuration value	3E.140 - 1 Low Voltage
Insulator	T: PTFE
Rated current	43 A
Test voltage (kV DC)	3.3

Form & Material

Shell style / Model id	HGP - Fixed receptacle, nut fixing, watertight or vacuum-tight
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Circular, female
Colour	Grey
Variant	Watertight / Vacuum-tested unmated (connector to device)
Weight	77.29 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	Hermetic unmated
Endurance	5000 mating cycles
Temperature range	-20°C / +80°C
Climatical Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Pressure	30 bars
R leak (He) (max)	0.0000001 mbar*l/s (if vacuum-tested)
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/hgp-3e-140-ctlpv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]	2.60 - 22.60 mm
------------------------------------	-----------------

Drawings

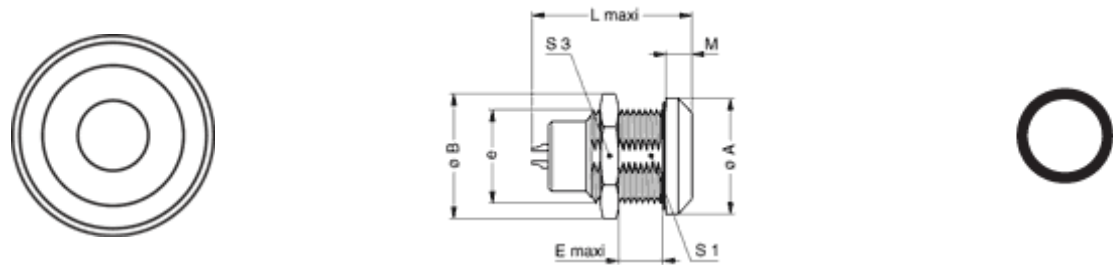

Dimensions

	B	e	E	L	M	S1	S3	A
mm.	34	M24x1.0	15.5	39.5	6	22.5	30	31
in.	1.34		0.61	1.56	0.24	0.89	1.18	1.22

Recommended By Lemo

Accessories

Compatible cap	BRE.3K.200.NAS
----------------	--------------------------------