



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Threaded
Size	1W
Series	W - Underwater

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	PCB - Straight
R (max)	3.6 mOhm
Insert configuration value	1W.303 - 3 Low Voltage
Rated current	12 A
Contact Type	Print (straight)
Contact Dia.	1.3 mm (0.051in)
Number of contacts Low Voltage	3
Gender	Standard

## Form & Material

Shell style / Model id	HV - Fixed socket, nut fixing, vacuumtight
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	G: 1 key (alpha=0, Plug: male contacts, Receptacle: female contacts)
Colour	Grey
Variant	Watertight / Vacuum-tested unmated (connector to device)
Weight	20.29 g


[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Environment

Technical domain	Specialties and Other
Environmental sealing (IP rating)	Hermetic unmated
Endurance	1000 mating cycles
Temperature range	-20°C / +100°C
Climatical Category	20/200/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	60 bars
R leak (He) (max)	0.0000001 mbar*/s (if vacuum-tested)
Salt Spray Corrosion	>1000 hr

## Drawings

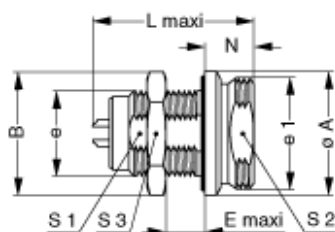

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>e1</b>	<b>E</b>	<b>L</b>	<b>N</b>	<b>S1</b>	<b>S2</b>	<b>S3</b>
mm.	18.3	19.5	M14x1.0	M16x1.0	11.5	30	8	12.5	14.5	17
in.	0.72	0.77			0.45	1.18	0.31	0.49	0.57	0.67

## Recommended By Lemo

### Accessories

Compatible cap

[BRE.1V.200.NAV](#)

[https://www.lemo.com/int\\_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html](https://www.lemo.com/int_en/solutions/supreme/w-underwater/hvg-1w-303-clnpv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.