



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	2
Number of contacts High Voltage	2
Nb of contacts Fiber optic	2
Wire Size/AWG	24 - 20
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	8.90 - 9.50 mm
Size	3K
Series	3K.93C.Y - SMPTE Hybrid

https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smp-te-hybrid/pbw-3k-93c-yscc96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	2
Contact Termination Low voltage	Crimp
Number of contacts High Voltage	2
Contact Termination High voltage	Crimp
Nb of contacts Fiber optic	2
Contact Termination Fiber optic	Crimp
Insert configuration value	3K.93C - 2 FO Type F2, 2 HV + 2 LV
Rated current	10 A
Fiber Optic Contact	Type F2
Vtest power/signal (AC)	2250V , 1000V
Working voltage power/signal(AC)	600V , 42V
Cable type	SMPTE 311M or EBU R100
Wire Size/AWG	24 - 20

Form & Material

Shell style / Model id	PB - Fixed receptacle 'Y design' with rear square flange (4 hole fixing), cable adapter, with bend relief nut
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Special housing (see notes for details)
Locking system	Push-pull
Keying	5 keys (alpha=95, beta=115, gamma=20, delta=30, plug: female LV, male HV, female FO contacts)
Variant	Nut for fitting a bend relief
Weight	91.93 g

https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/pbw-3k-93c-yscc96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Environmental sealing (IP rating)	IP68
Endurance	20000 mating cycles
Temperature range	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	8.90 - 9.50 mm

Drawings

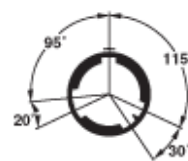

Dimensions

	A	L	M	F	H	G
mm.	29	133.5	22.5	3	23	3.5
in.	1.14	5.26	0.89	0.12	0.91	0.14

https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/pbw-3k-93c-yscc96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Replacement contact	FGG.3B.560.ZZC
Compatible cap	BRA.3K.100.715EN
Tools	
Fiber Tool	WST.KI.125.34
Fiber Tool 2	DCB.91.119.0TN
Positionner	DCE.91.093.BVC
Positionner 2	DCE.91.133.BVCW
Extraction tool	DCC.09.05B.LAG
Extraction tool 2	DCC.13.15B.LAG
Crimp tool	DPC.91.701.V
Crimp Tool 2	DPC.91.101.A
Spanner wrench	DCD.3E.ZZZ.PA150