

Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Wire Size/AWG	28 - 20
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.60 - 5.00 mm
Size	1E
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	1E.302/ThC - 1 Thermocouple Pair
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	15 Amps
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	1.3
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/pca-1e-302-slk50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	PCA - Free receptacle, cable collet
Socket / Receptacle	Free
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	24.61 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]



Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.60 - 5.00 mm

Drawings

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/pca-1e-302-slk50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

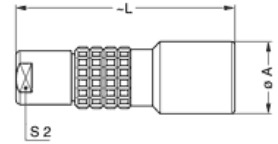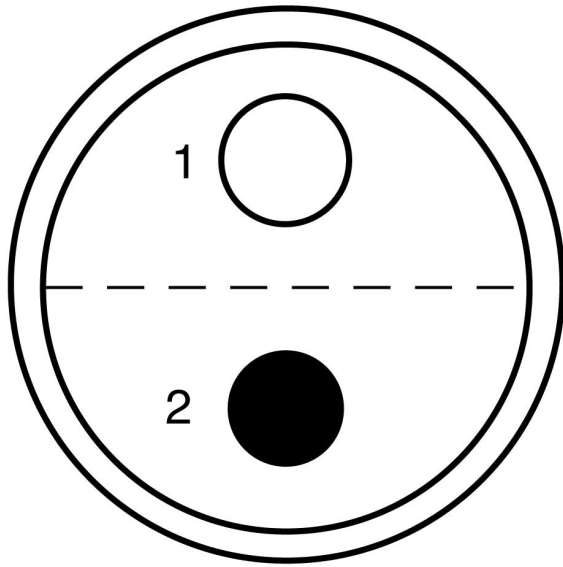

Contact 1: Alumel (-)
 Contact 2: Chromel (+)

Dimensions

	A	L	S 2
mm.	15	45	9
in.	0.59	1.77	0.35

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/pca-1e-302-slk50.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.