



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	4
Wire Size/AWG	30 - 22
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Size	1S
Suggested matching part	FFA.1S.902.CLKF42
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pca-1s-902-clkf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Thermocouple	4
Contact Termination Thermocouple	Solder
Insert configuration value	1S.902/ThC - 2 Thermocouple Pairs
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
Thermocouple (P+/N-)	Pin 3 / Pin 4
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	0.9
Wire Size/AWG	30 - 22

Form & Material

Shell style / Model id	PCA - Free receptacle, cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	19.06 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pca-1s-902-clkf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation



Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

Drawings

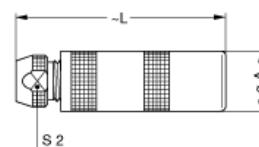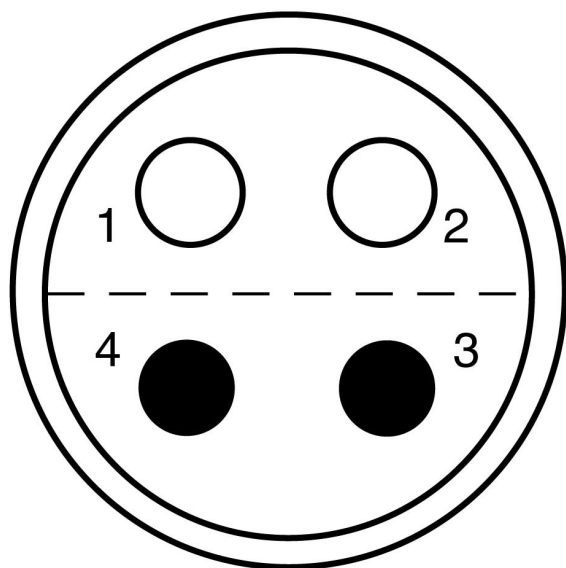

Contact 1, 3: Chromel (+)
Contact 2, 4: Alumel (-)

Dimensions

	A	L	S2	C
mm.	11.9	40.5	8.5	6.2
in.	0.47	1.59	0.33	0.24

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pca-1s-902-clkf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Compatible cap

[BRF.1S.200.NAS](#)

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/pca-1s-902-clkf42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.