



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	14
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	6.60 - 7.00 mm
Size	2K
Suggested matching part	<a href="#">FGG.2K.314.CLAC70Z</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	6.1 mOhm
Insert configuration value	2K.314 - 14 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	6.5 A
Vtest (contact-contact)	1150 V (AC), 1630 V (DC)
Vtest (contact-shell)	1350 V (AC), 1910 V (DC)
Contact Type	Solder
Max. Solid Conductor	0.34 mm <sup>2</sup> (AWG 22)
Max. Stranded Conductor	0.34 mm <sup>2</sup> (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Number of contacts Low Voltage	14
Wire Size/AWG	30 - 22
Gender	Standard

## Form & Material

Shell style / Model id	PE - Fixed receptacle, nut fixing, cable adapter, with bend relief nut (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	59.07 g

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	6.60 - 7.00 mm

## Drawings

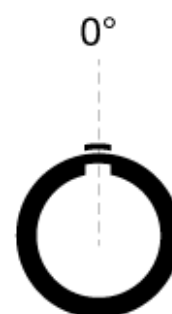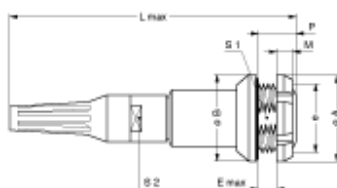

## Dimensions

	A	P	M	L	E	e	B	S1	S2
mm.	25	7.5	3.5	103	4	M20x1.0	25	18.5	12
in.	0.98	0.3	0.14	4.06	0.16		0.98	0.73	0.47

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Accessories

---






## Tools

---

Spanner wrench

[Socket for torque wrench DCM.2E.M20.6](#)

# Cables

Cable PartNumber	Material	Colour	Cable image
CMN.14.T22.068PGCE	PVC	GREY	
CMN.14.T22.068PGZE		grey	
CMN.14.T22.068PNCE	PVC	Black	
CMN.14.T22.068PNZE			
214140	PVC	Black	

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/peg-2k-314-cllc70z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.