



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	2
Number of contacts High Voltage	2
Nb of contacts Fiber optic	2
Wire Size/AWG	24 - 20
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	8.90 - 9.50 mm
Size	3K
Series	3K.93C.Y - SMPTE Hybrid

https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smp-te-hybrid/pew-3k-93c-ysec96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	2
Contact Termination Low voltage	Crimp
Number of contacts High Voltage	2
Contact Termination High voltage	Crimp
Nb of contacts Fiber optic	2
Insert configuration value	3K.93C - 2 FO Type F2, 2 HV + 2 LV
Rated current	10 A
Cable type	SMPTE 311M or EBU R100
Wire Size/AWG	24 - 20

Form & Material

Shell style / Model id	PE - Fixed receptacle, nut fixing, cable adapter, with bend relief nut (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Special housing (see notes for details)
Locking system	Push-pull
Keying	5 keys (alpha=95, beta=115, gamma=20, delta=30, plug: female LV, male HV, female FO contacts)
Variant	Nut for fitting a bend relief
Weight	104.45 g

Environment

Environmental sealing (IP rating)	IP68
Endurance	20000 mating cycles
Temperature range	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]



https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/pew-3k-93c-ysec96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	8.90 - 9.50 mm

Drawings

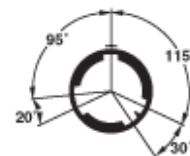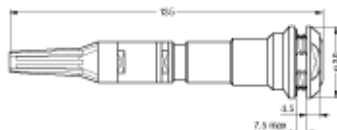

Dimensions

	M	E	A	L
mm.	4.5	7.5	30	135
in.	0.18	0.3	1.18	5.31

Recommended By Lemo

Accessories

Replacement contact	FGG.3B.560.ZZC
Compatible cap	BRA.3K.200.EAN

Tools

Fiber Tool	WST.KI.125.34
Fiber Tool 2	DCB.91.119.0TN
Spanner	DCP.91.023.TN
Positionner	DCE.91.093.BVC
Positionner 2	DCE.91.133.BVCW
Extraction tool	DCC.09.05B.LAG
Extraction tool 2	DCC.13.15B.LAG
Spanner wrench	Socket for torque wrench DCM.65.270.AZ

https://www.lemo.com/int_en/solutions/specialties/3k-93c-y-smpte-hybrid/pew-3k-93c-ysec96z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.