

*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	4
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Size	2B
Suggested matching part	<a href="#">FGG.2B.902.CLKF82</a>
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Thermocouple	4
Contact Termination Thermocouple	Solder
Insert configuration value	2B.902/ThC - 2 Thermocouple Pairs
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	15 A
Thermocouple (P+/N-)	Pin 3 / Pin 4
Gender	Standard

## Form & Material

Shell style / Model id	PH - Free receptacle, cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	36.87 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

 


Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

## Drawings

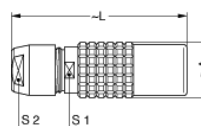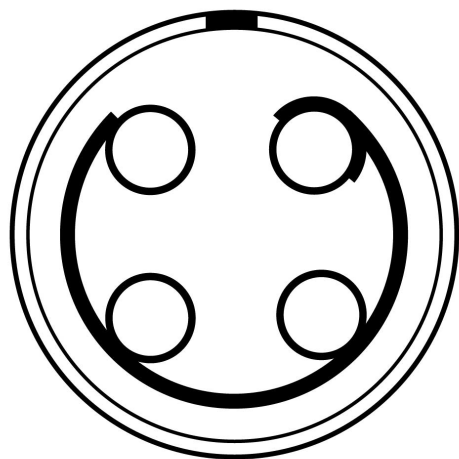

Contact 1, 3: Chromel (+)

Contact 2, 4: Alumel (-)

## Dimensions

	<b>S2</b>	<b>S1</b>	<b>L</b>	<b>A</b>
mm.	12	13	47	16.5
in.	0.47	0.51	1.85	0.65

## Recommended By Lemo

### Accessories

Compatible cap

[BRF.2S.200.NAS](#)

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-2b-902-clkf82.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.