

Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	5
Wire Size/AWG	28 - 20
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Size	2L
Matching parts	FGG.2L.305.CLAC70

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Contact Type	Solder
Contact Dia.	1.3
Low Voltage	5
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/phg-2l-305-cllc70.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	PH - Free socket, cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Weight	45.05 g


Environment

Environmental protection (IP rating)	IP66
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
------------------------------	--

Drawings

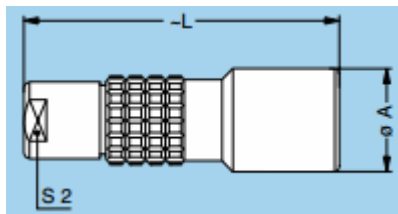

Dimensions

	A	L	S2
mm.	19	54	12
in.	0.75	2.13	0.47

https://www.lemo.com/int_en/phg-2l-305-cllc70.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.