

Summary

[Request a quote](#)

[Catalog](#)

Low Voltage	6
Wire Size/AWG	20 - 18
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Size	2L

Technical details

Electrical Configuration

Contact Termination Low voltage	Crimp
Contact Type	Crimp
Contact Dia.	1.3
Low Voltage	6
Wire Size/AWG	20 - 18

Form & Material

Shell style / Model id	PH - Free socket, cable collet and nut for fitting a bend relief
Socket / Receptacle	Free
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Variant	Nut for fitting a bend relief

https://www.lemo.com/int_en/phg-2l-306-yilmc82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Environmental protection (IP rating)


IP66

Cable fixation

Cable termination protection

Standard back nut (no additional protection)

Drawings

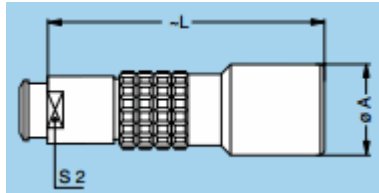

Dimensions

	A	L	S2
mm.	19	54	12
in.	0.75	2.13	0.47

https://www.lemo.com/int_en/phg-2l-306-ylmc82z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.