

Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	20
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	10.80 - 11.90 mm
Size	3B
Suggested matching part	FGG.3B.320.CYKD12
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-3b-320-cykd12.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Thermocouple	20
Contact Termination Thermocouple	Crimp
Insert configuration value	3B.320 - 10 Thermocouple Pairs
Insulator	Y: PEEK for crimp contacts
Rated current	6 A
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	0.7
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	PH - Free receptacle, cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-3b-320-cykd12.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.80 - 11.90 mm

Drawings

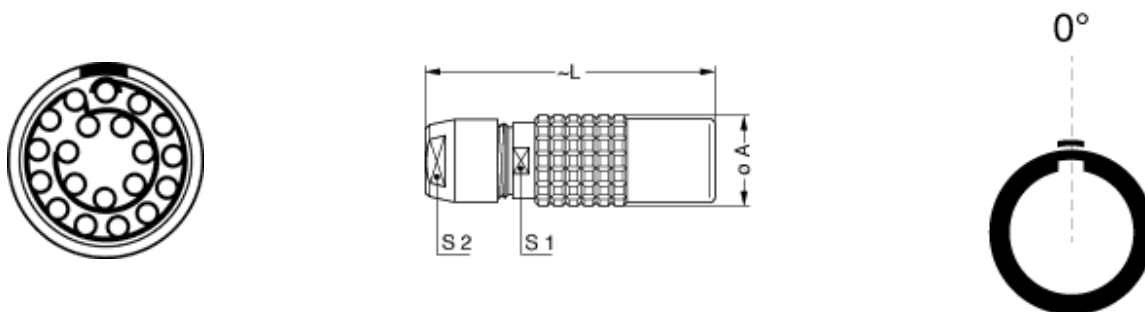

Dimensions

	A	S1	S2	L
mm.	19	15	14	56
in.	0.75	0.59	0.55	2.2

Recommended By Lemo

Accessories

Replacement contact	EGG.3B.655.ZZK
Compatible cap	BRF.3S.200.NAS

Tools

Spanner	DCP.91.023.TN
Spanner wrench	DCD.3B.ZZZ.PA140

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/phg-3b-320-cykd12.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.