

*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

Number of contacts Low Voltage	4
Number of contacts High Voltage	2
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Free
Locking system	Push-pull
Jacket cable outside diameter [mm]	10.60 - 12.00 mm
Size	3K
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Solder
Number of contacts High Voltage	2
Contact Termination High voltage	Solder
Insert configuration value	3K.7H4 - 2 High V. 2 Low V.
Insulator	J: PEEK/PEEK
Rated current	2 A
Gender	Standard

## Form & Material

Shell style / Model id	PH - Free receptacle with oversize cable collet
Socket / Receptacle	Free
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	126.52 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.60 - 12.00 mm

## Drawings

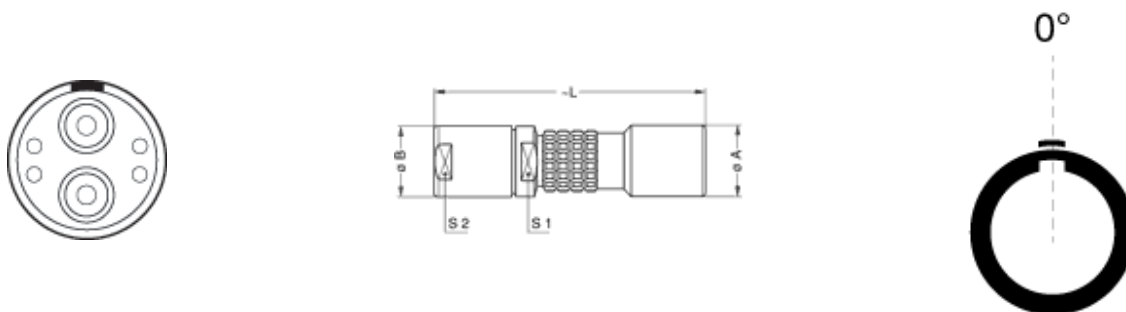

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>S2</b>	<b>S1</b>
mm.	23	22	89	19	19
in.	0.91	0.87	3.5	0.75	0.75

## Recommended By Lemo

### Accessories

Compatible cap

[BRF.3K.200.NAS](#)

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/phg-3k-7h4-cjlk11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.