



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fiber optic	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Size	00
Suggested matching part	<a href="#">FGG.00.BA4.CCBE30Z</a>

# Technical details

## Electrical Configuration

Nb of contacts Fiber optic	1
Insert configuration value	FO/BA4 - 1 FO 125 um hole
Insulator	C: Zirconia Ceramic
Core/Cladding (um)	9/125
Ferrule Material	Zirconia Ceramic
Hole dia.(um)	125
Contact Type	F4 (included)

## Form & Material

Shell style / Model id	PK - Fixed receptacle, nut fixing, with bend relief included
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	10.1 g

## Environment

Environmental sealing (IP rating)	IP50
Salt Spray Corrosion	>1000 hr


## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Crimp

# Drawings

[https://www.lemo.com/int\\_en/pkg-00-ba4-ccse30z.html](https://www.lemo.com/int_en/pkg-00-ba4-ccse30z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

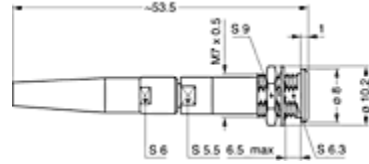

## Dimensions

	<b>S1</b>	<b>S2</b>	<b>S3</b>	<b>L</b>	<b>M</b>	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>
mm.	8.2	7	11	35.5	1.2	10	12.4	M9x0.6	7
in.	0.32	0.28	0.43	1.4	0.05	0.39	0.49		0.28

## Recommended By Lemo

### Accessories

Compatible cap

[BRA.00.200.PCSG](#)

[https://www.lemo.com/int\\_en/pkg-00-ba4-ccse30z.html](https://www.lemo.com/int_en/pkg-00-ba4-ccse30z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.