



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	2
Wire Size/AWG	28 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.30 - 3.20 mm
Size	0B
Suggested matching part	FGG.0B.302.CYKD32
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkg-0b-302-cykd32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Thermocouple	2
Contact Termination Thermocouple	Crimp
Insert configuration value	0B.302 - 1 Thermocouple Pair
Insulator	Y: PEEK for crimp contacts
Rated current	10 A
Thermocouple (P+/N-)	Pin 1 / Pin 2
Vtest (contact-shell)	900 V (AC), 1270 V (DC)
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	0.9
Wire Size/AWG	28 - 20
Gender	Standard
Important recommendation	Contact LEMO for performance details.

Form & Material

Shell style / Model id	PK - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkg-0b-302-cykd32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

 


Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.30 - 3.20 mm

Drawings

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkg-0b-302-cykd32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

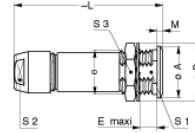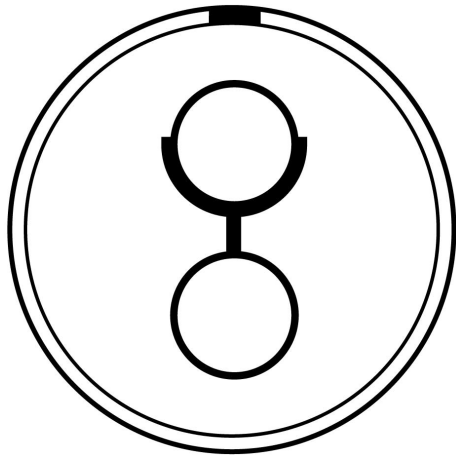

Contact 1: Chromel (+)
Contact 2: Alumel (-)

Dimensions

	S1	S2	S3	L	M	A	B	e	E
mm.	8.2	7	11	35.5	1.2	10	12.4	M9x0.6	7
in.	0.32	0.28	0.43	1.4	0.05	0.39	0.49		0.28

Recommended By Lemo

Accessories

Replacement contact	EGG.0B.660.ZZK
Compatible cap	BRA.0B.200.PCSG

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/pkg-0b-302-cykd32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.