



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	2
Wire Size/AWG	30 - 22
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.60 - 4.00 mm
Size	0E
Suggested matching part	<a href="#">FFA.0E.302.CLAC40</a>
Series	E - Outdoor Stepped Insert

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	2
Contact Termination Low voltage	Solder
R (max)	4.8 mOhm
Insert configuration value	0E.302 - 2 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
Test voltage (kV DC)	1.6
Max. Solid Conductor	0.34 mm <sup>2</sup> (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.9 mm (0.0354in)
Wire Size/AWG	30 - 22

## Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Colour	Grey
Weight	18.85 g

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.60 - 4.00 mm

## Drawings

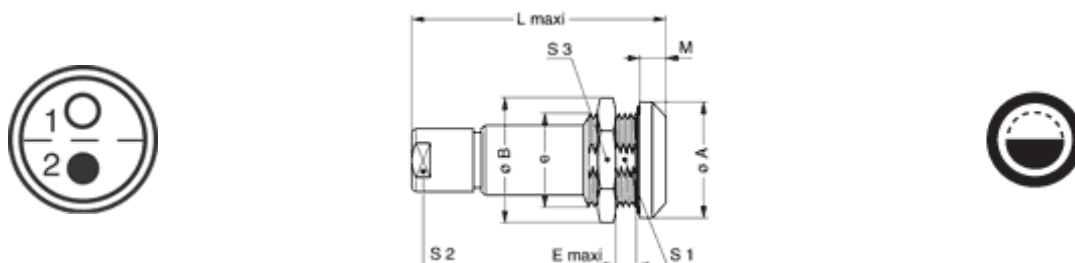

## Dimensions

	A	B	e	E	L	M	S1	S2	S3
mm.	18	19.5	M14x1.0	5.5	34	4	12.5	8	17
in.	0.71	0.77		0.22	1.34	0.16	0.49	0.31	0.67

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-0e-302-cllc40.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.











# Recommended By Lemo

## Accessories

Compatible cap

BRE.0K.200.NAS

## Cables

Cable PartNumber	Material	Colour	Cable image
20140	PVC	Grey	
20140	PVC	Grey	
20141	PVC	Grey	
20142	PVC	Red	
20143	PVC	Green	
20144	PVC	Black	
20145	PVC	Yellow	
20146	PVC	Black	
20264	PVC	Black	
20266	PVC	Violet	
2280	PVC	Black	