



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Wire Size/AWG	26 - 22
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.30 - 3.20 mm
Size	0S
Suggested matching part	FFA.0S.304.CYCC32
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-0s-304-cymc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Crimp
Insert configuration value	0S.304 - 4 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	7 A
Test voltage (kV DC)	1.5
Contact Dia.	0.7
Wire Size/AWG	26 - 22

Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Colour	Grey

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-0s-304-cymc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.30 - 3.20 mm

Drawings

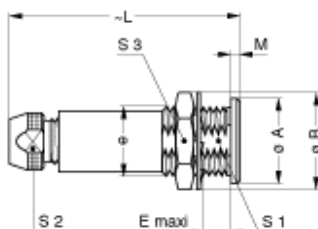

Dimensions

	A	B	e	E	L	M	S1	S2	S3	C
mm.	10	12.5	M9x0.6	7	33.5	1.2	8.2	6.5	11	4.2
in.	0.39	0.49		0.28	1.32	0.05	0.32	0.26	0.43	0.17

Recommended By Lemo

Accessories

Replacement contact	FGG.0B.555.ZZC
Compatible cap	BRA.0B.200.PCSG

Tools

Positionner	DCE.91.070.BVM
Extraction tool	DCC.07.04B.LAG
Crimp tool	DPC.91.701.V
Spanner wrench	DCD.0S.ZZZ.PA065

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-0s-304-cymc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.