



Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Wire Size/AWG	22 - 14
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	6.10 - 6.50 mm
Size	3E
Suggested matching part	FFA.3E.303.CLAC65
Series	E - Outdoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-3e-303-cllc65.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	3E.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	20 A
Vtest	1500 V (AC), 2100 V (DC)
Contact Type	Solder
Bucket Dia.	1.8
Contact Dia.	2
Number of contacts Low Voltage	3
Wire Size/AWG	22 - 14

Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Weight	111.66 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-3e-303-cllc65.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	6.10 - 6.50 mm

Drawings

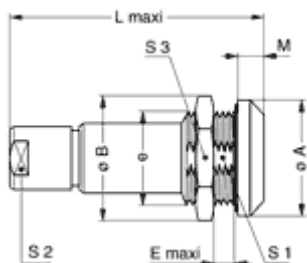

Dimensions

	A	B	e	E	L	M	S1	S2	S3
mm.	31	34.5	M24x1.0	11	65	6	22.5	15	30
in.	1.22	1.36		0.43	2.56	0.24	0.89	0.59	1.18

Recommended By Lemo

Accessories

Tools

Spanner wrench

[DCD.3E.ZZZ.PA150](#)

Cables

Cable PartNumber	Material	Colour	Cable image
230750	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/psa-3e-303-cllc65.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.