



## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Triax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	11.10 - 12.00 mm
Size	4S
Matching parts	<a href="#">FFA.4S.675.CTAC12</a>
Series	S - Indoor Stepped Insert

## Technical details

### Electrical Configuration

Nb of contacts Triax	1
Contact Termination Triax	Solder
Insert configuration value	4S.675 - 1 Triax (75 Ohm)
Insulator	T: PTFE
Rated current	15 Amps
Impedance	75 Ohm
VSWR	1.01 + 0.14 * f/GHz
Vtest	1500 V (AC), 2100 V (DC)
Contact Type	Solder
Cable type	Cable type: A Belden 8215,8232A,HF-2426,Triax 8 Nokia,375 029 LEDE, Belden 9267,8233A, Triax 11 Nokia,466 140 LEDE S

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	PSA - Fixed receptacle, nut fixing, cable collet
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Weight	151.56 g


## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	11.10 - 12.00 mm

## Drawings

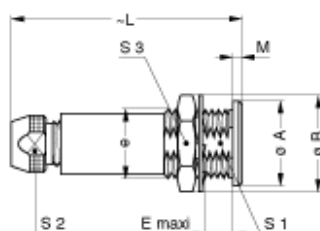

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>S1</b>	<b>S2</b>	<b>S3</b>
mm.	28	32	M25x1.0	12	75	2.5	23.5	19	30
in.	1.1	1.26		0.47	2.95	0.1	0.93	0.75	1.18

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/psa-4s-675-ctlc12.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.